


# 2GT

〈ピッチ:2.0mm〉

## ● ベルト歯形寸法

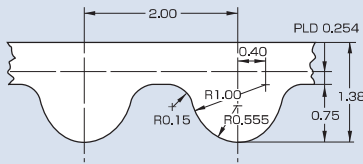

## ● ベルト呼称例

### 200-2GT-4

幅(mm)  
タイプ記号  
ピッチ周長(mm)

## ベルトサイズ一覧表

呼称	ピッチ周長(mm)	歯数
54-2GT	54.00	27
58-2GT	58.00	29
60-2GT	60.00	30
66-2GT	66.00	33
72-2GT	72.00	36
74-2GT	74.00	37
76-2GT	76.00	38
78-2GT	78.00	39
80-2GT	80.00	40
82-2GT	82.00	41
84-2GT	84.00	42
86-2GT	86.00	43
88-2GT	88.00	44
90-2GT	90.00	45
92-2GT	92.00	46
94-2GT	94.00	47
96-2GT	96.00	48
98-2GT	98.00	49
100-2GT	100.00	50
102-2GT	102.00	51
106-2GT	106.00	53
108-2GT	108.00	54
110-2GT	110.00	55
112-2GT	112.00	56
114-2GT	114.00	57
116-2GT	116.00	58
118-2GT	118.00	59
120-2GT	120.00	60
122-2GT	122.00	61
124-2GT	124.00	62
126-2GT	126.00	63
128-2GT	128.00	64
130-2GT	130.00	65
132-2GT	132.00	66
134-2GT	134.00	67
136-2GT	136.00	68
138-2GT	138.00	69
140-2GT	140.00	70
142-2GT	142.00	71
144-2GT	144.00	72
146-2GT	146.00	73
148-2GT	148.00	74
150-2GT	150.00	75
152-2GT	152.00	76
154-2GT	154.00	77
156-2GT	156.00	78
158-2GT	158.00	79
160-2GT	160.00	80
162-2GT	162.00	81
164-2GT	164.00	82
166-2GT	166.00	83
168-2GT	168.00	84
170-2GT	170.00	85
172-2GT	172.00	86
174-2GT	174.00	87
176-2GT	176.00	88
178-2GT	178.00	89
180-2GT	180.00	90
182-2GT	182.00	91
184-2GT	184.00	92
186-2GT	186.00	93
188-2GT	188.00	94
190-2GT	190.00	95
192-2GT	192.00	96
194-2GT	194.00	97
196-2GT	196.00	98
200-2GT	200.00	100
202-2GT	202.00	101
204-2GT	204.00	102
206-2GT	206.00	103
208-2GT	208.00	104
210-2GT	210.00	105
212-2GT	212.00	106
214-2GT	214.00	107
216-2GT	216.00	108
220-2GT	220.00	110
224-2GT	224.00	112
226-2GT	226.00	113
228-2GT	228.00	114
230-2GT	230.00	115

呼称	ピッチ周長(mm)	歯数
232-2GT	232.00	116
236-2GT	236.00	118
240-2GT	240.00	120
242-2GT	242.00	121
244-2GT	244.00	122
248-2GT	248.00	124
250-2GT	250.00	125
252-2GT	252.00	126
254-2GT	254.00	127
256-2GT	256.00	128
258-2GT	258.00	129
260-2GT	260.00	130
264-2GT	264.00	132
266-2GT	266.00	133
268-2GT	268.00	134
270-2GT	270.00	135
278-2GT	278.00	139
280-2GT	280.00	140
282-2GT	282.00	141
284-2GT	284.00	142
286-2GT	286.00	143
288-2GT	288.00	144
290-2GT	290.00	145
292-2GT	292.00	146
294-2GT	294.00	147
300-2GT	300.00	150
302-2GT	302.00	151
304-2GT	304.00	152
308-2GT	308.00	154
310-2GT	310.00	155
314-2GT	314.00	157
318-2GT	318.00	159
320-2GT	320.00	160
322-2GT	322.00	161
324-2GT	324.00	162
326-2GT	326.00	163
328-2GT	328.00	164
332-2GT	332.00	166
336-2GT	336.00	168
338-2GT	338.00	169
340-2GT	340.00	170
344-2GT	344.00	172
346-2GT	346.00	173
348-2GT	348.00	174
350-2GT	350.00	175
352-2GT	352.00	176
354-2GT	354.00	177
358-2GT	358.00	179
360-2GT	360.00	180
366-2GT	366.00	183
370-2GT	370.00	185
372-2GT	372.00	186
376-2GT	376.00	188
380-2GT	380.00	190
382-2GT	382.00	191
386-2GT	386.00	193
394-2GT	394.00	197
400-2GT	400.00	200
406-2GT	406.00	203
412-2GT	412.00	206
420-2GT	420.00	210
426-2GT	426.00	213
430-2GT	430.00	215
436-2GT	436.00	218
440-2GT	440.00	220
444-2GT	444.00	222
446-2GT	446.00	223
448-2GT	448.00	224
452-2GT	452.00	226
454-2GT	454.00	227
460-2GT	460.00	230
470-2GT	470.00	235
478-2GT	478.00	239
484-2GT	484.00	242
486-2GT	486.00	243
488-2GT	488.00	244
492-2GT	492.00	246
494-2GT	494.00	247
500-2GT	500.00	250
502-2GT	502.00	251

呼称	ピッチ周長(mm)	歯数
504-2GT	504.00	252
506-2GT	506.00	253
508-2GT	508.00	254
516-2GT	516.00	258
524-2GT	524.00	262
530-2GT	530.00	265
544-2GT	544.00	272
550-2GT	550.00	275
558-2GT	558.00	279
570-2GT	570.00	285
572-2GT	572.00	286
578-2GT	578.00	289
586-2GT	586.00	293
598-2GT	598.00	299
600-2GT	600.00	300
606-2GT	606.00	303
616-2GT	616.00	308
630-2GT	630.00	315
634-2GT	634.00	317
646-2GT	646.00	323
660-2GT	660.00	330
670-2GT	670.00	335
676-2GT	676.00	338
690-2GT	690.00	345
696-2GT	696.00	348
702-2GT	702.00	351
726-2GT	726.00	363
742-2GT	742.00	371
752-2GT	752.00	376
760-2GT	760.00	380
772-2GT	772.00	386
782-2GT	782.00	391
800-2GT	800.00	400
810-2GT	810.00	405
828-2GT	828.00	414
852-2GT	852.00	426
860-2GT	860.00	430
866-2GT	866.00	433
892-2GT	892.00	446
900-2GT	900.00	450
930-2GT	930.00	465
950-2GT	950.00	475
976-2GT	976.00	488
994-2GT	994.00	497
1004-2GT	1004.00	502
1028-2GT	1028.00	514
1066-2GT	1066.00	533
1068-2GT	1068.00	534
1078-2GT	1078.00	539
1110-2GT	1110.00	555
1140-2GT	1140.00	570
1164-2GT	1164.00	582
1166-2GT	1166.00	583
1180-2GT	1180.00	590
1210-2GT	1210.00	605
1228-2GT	1228.00	614
1234-2GT	1234.00	617
1256-2GT	1256.00	628
1310-2GT	1310.00	655
1320-2GT	1320.00	660
1344-2GT	1344.00	672
1360-2GT	1360.00	680
1434-2GT	1434.00	717
1524-2GT	1524.00	762
1660-2GT	1660.00	830
1688-2GT	1688.00	844
1700-2GT	1700.00	850
1810-2GT	1810.00	905
1850-2GT	1850.00	925
1860-2GT	1860.00	930
1910-2GT	1910.00	955
2218-2GT	2218.00	1109

注) 周長994.0mm以上で幅2.5mm以下のベルトは製作できません。