


EV8YU

(ピッチ:8.0mm)


● ベルト歯形寸法

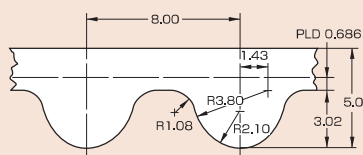

※GT8YUは5.2mmになります。

● ベルト呼称例

2000-EV8YU-40

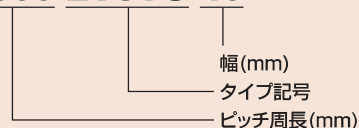

ベルトサイズ一覧表

呼称	ピッチ周長(mm)	歯数	呼称	ピッチ周長(mm)	歯数	呼称	ピッチ周長(mm)	歯数
312-EV8YU	312.00	39	1016-EV8YU	1016.00	127	1688-EV8YU	1688.00	211
328-EV8YU	328.00	41	1032-EV8YU	1032.00	129	1696-EV8YU	1696.00	212
344-EV8YU	344.00	43	1040-EV8YU	1040.00	130	1720-EV8YU	1720.00	215
408-EV8YU	408.00	51	1056-EV8YU	1056.00	132	1728-EV8YU	1728.00	216
416-EV8YU	416.00	52	1064-EV8YU	1064.00	133	1736-EV8YU	1736.00	217
432-EV8YU	432.00	54	1072-EV8YU	1072.00	134	1752-EV8YU	1752.00	219
440-EV8YU	440.00	55	1080-EV8YU	1080.00	135	1760-EV8YU	1760.00	220
464-EV8YU	464.00	58	1088-EV8YU	1088.00	136	1768-EV8YU	1768.00	221
472-EV8YU	472.00	59	1096-EV8YU	1096.00	137	1776-EV8YU	1776.00	222
480-EV8YU	480.00	60	1112-EV8YU	1112.00	139	1784-EV8YU	1784.00	223
488-EV8YU	488.00	61	1120-EV8YU	1120.00	140	1800-EV8YU	1800.00	225
504-EV8YU	504.00	63	1128-EV8YU	1128.00	141	1808-EV8YU	1808.00	226
512-EV8YU	512.00	64	1136-EV8YU	1136.00	142	1816-EV8YU	1816.00	227
520-EV8YU	520.00	65	1144-EV8YU	1144.00	143	1824-EV8YU	1824.00	228
536-EV8YU	536.00	67	1152-EV8YU	1152.00	144	1856-EV8YU	1856.00	232
544-EV8YU	544.00	68	1160-EV8YU	1160.00	145	1864-EV8YU	1864.00	233
552-EV8YU	552.00	69	1168-EV8YU	1168.00	146	1872-EV8YU	1872.00	234
560-EV8YU	560.00	70	1176-EV8YU	1176.00	147	1888-EV8YU	1888.00	236
576-EV8YU	576.00	72	1184-EV8YU	1184.00	148	1896-EV8YU	1896.00	237
600-EV8YU	600.00	75	1192-EV8YU	1192.00	149	1912-EV8YU	1912.00	239
608-EV8YU	608.00	76	1200-EV8YU	1200.00	150	1928-EV8YU	1928.00	241
616-EV8YU	616.00	77	1208-EV8YU	1208.00	151	1944-EV8YU	1944.00	243
624-EV8YU	624.00	78	1216-EV8YU	1216.00	152	1952-EV8YU	1952.00	244
632-EV8YU	632.00	79	1224-EV8YU	1224.00	153	1976-EV8YU	1976.00	247
640-EV8YU	640.00	80	1232-EV8YU	1232.00	154	2000-EV8YU	2000.00	250
656-EV8YU	656.00	82	1240-EV8YU	1240.00	155	2056-EV8YU	2056.00	257
664-EV8YU	664.00	83	1248-EV8YU	1248.00	156	2072-EV8YU	2072.00	259
680-EV8YU	680.00	85	1256-EV8YU	1256.00	157	2120-EV8YU	2120.00	265
704-EV8YU	704.00	88	1264-EV8YU	1264.00	158	2136-EV8YU	2136.00	267
720-EV8YU	720.00	90	1272-EV8YU	1272.00	159	2160-EV8YU	2160.00	270
728-EV8YU	728.00	91	1280-EV8YU	1280.00	160	2240-EV8YU	2240.00	280
744-EV8YU	744.00	93	1288-EV8YU	1288.00	161	2248-EV8YU	2248.00	281
752-EV8YU	752.00	94	1296-EV8YU	1296.00	162	2264-EV8YU	2264.00	283
760-EV8YU	760.00	95	1304-EV8YU	1304.00	163	2280-EV8YU	2280.00	285
768-EV8YU	768.00	96	1312-EV8YU	1312.00	164	2296-EV8YU	2296.00	287
776-EV8YU	776.00	97	1320-EV8YU	1320.00	165	2304-EV8YU	2304.00	288
784-EV8YU	784.00	98	1328-EV8YU	1328.00	166	2328-EV8YU	2328.00	291
792-EV8YU	792.00	99	1336-EV8YU	1336.00	167	2368-EV8YU	2368.00	296
800-EV8YU	800.00	100	1344-EV8YU	1344.00	168	2400-EV8YU	2400.00	300
808-EV8YU	808.00	101	1352-EV8YU	1352.00	169	2456-EV8YU	2456.00	307
816-EV8YU	816.00	102	1360-EV8YU	1360.00	170	2600-EV8YU	2600.00	325
824-EV8YU	824.00	103	1376-EV8YU	1376.00	172	2712-EV8YU	2712.00	339
832-EV8YU	832.00	104	1384-EV8YU	1384.00	173	2768-EV8YU	2768.00	346
840-EV8YU	840.00	105	1392-EV8YU	1392.00	174	2800-EV8YU	2800.00	350
848-EV8YU	848.00	106	1400-EV8YU	1400.00	175	2944-EV8YU	2944.00	368
856-EV8YU	856.00	107	1408-EV8YU	1408.00	176	3144-EV8YU	3144.00	393
864-EV8YU	864.00	108	1416-EV8YU	1416.00	177	3200-EV8YU	3200.00	400
872-EV8YU	872.00	109	1424-EV8YU	1424.00	178	3440-EV8YU	3440.00	430
880-EV8YU	880.00	110	1432-EV8YU	1432.00	179	3600-EV8YU	3600.00	450
888-EV8YU	888.00	111	1440-EV8YU	1440.00	180	3848-EV8YU	3848.00	481
896-EV8YU	896.00	112	1448-EV8YU	1448.00	181	3920-EV8YU	3920.00	490
904-EV8YU	904.00	113	1456-EV8YU	1456.00	182	4400-EV8YU	4400.00	550
912-EV8YU	912.00	114	1464-EV8YU	1464.00	183	5008-EV8YU	5008.00	626
920-EV8YU	920.00	115	1480-EV8YU	1480.00	185			
928-EV8YU	928.00	116	1496-EV8YU	1496.00	187			
936-EV8YU	936.00	117	1520-EV8YU	1520.00	190			
944-EV8YU	944.00	118	1544-EV8YU	1544.00	193			
952-EV8YU	952.00	119	1568-EV8YU	1568.00	196			
960-EV8YU	960.00	120	1576-EV8YU	1576.00	197			
968-EV8YU	968.00	121	1600-EV8YU	1600.00	200			
976-EV8YU	976.00	122	1608-EV8YU	1608.00	201			
984-EV8YU	984.00	123	1616-EV8YU	1616.00	202			
992-EV8YU	992.00	124	1640-EV8YU	1640.00	205			
1000-EV8YU	1000.00	125	1656-EV8YU	1656.00	207			
1008-EV8YU	1008.00	126	1680-EV8YU	1680.00	210			

●EV8YUタイプでは、特殊仕様品は製作できません。特殊仕様品は、「GTベルト:8YUタイプ」にてご検討ください。